

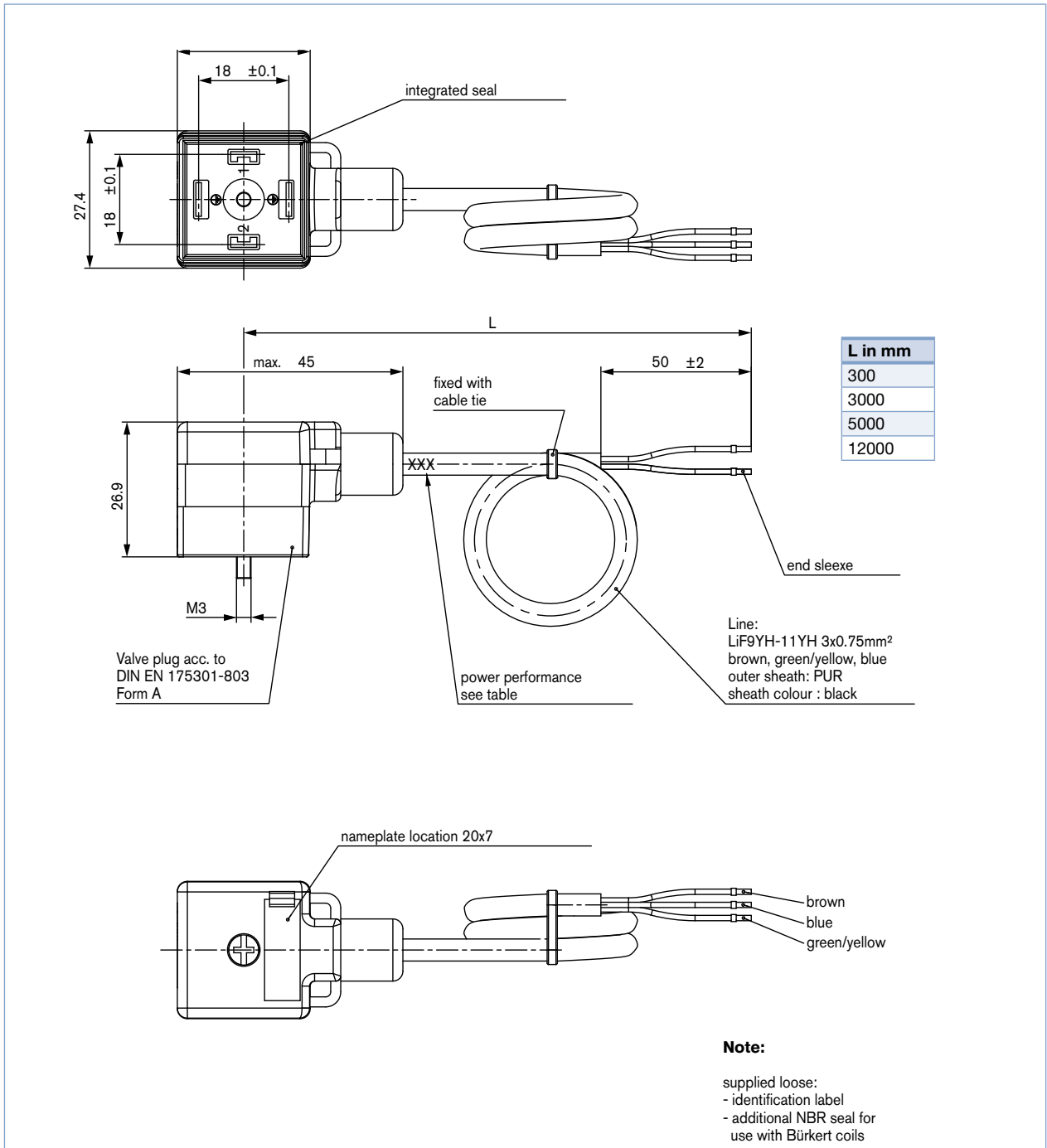
Cable plug acc. to DIN EN 175 301-803 Form A

- Meets the requirements of ATEX category 3 GD
- Impact and extract test acc. to EN 60079 standard
- TAG sign for individual labelling
- Hard prewired PUR cable in 4 lengths

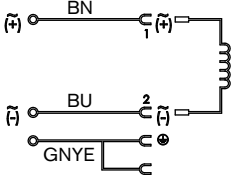

 
 

Connector with fixed molded cable for connecting electrical components according to DIN EN 175 301-803.

Technical data	
Plug	
No. of pins	4 pin (2 + 2x protective conductor)
Body material	Polyamide
Contact material	Brass , silver plated
Circuit	Without
Fixing screw	St.st
Seal	TPU injected additional NBR*1 (supplied loose)
Cable specification	
Cable diameter	5.5... 6.5 mm
Cable sheath	PUR
Core insulation	PP
Core cross-section	3 x 0.75mm ²
Bending radius (moving state)	Min. 10x cable diameter
Sheath color	Black
Core insulation color	BN,BU,GNYE
Electrical specification	
Acceptable current load	4 A
Rated voltage	max. 230 V AC/DC
Environmental conditions	
Protection class	IP65 (in locked position)
Ambient temperature	-30 °C to +90 °C
Soiling level	3

Dimensions [mm]



Ordering chart

	Cable length [mm]	Item no. [in mm]
	12000	260893 
	5000	260892 
	3000	260891 
	300	260890 

To find your nearest Bürkert facility, click on the orange box → www.burkert.com