

3/2-, 5/2- and 5/3-way solenoid valve
3/2-, 5/2- und 5/3-Wege-Magnetventil
Électrovanne à 3/2, 5/2 et 5/3 voies

Address / Adresse

Bürkert Fluid Control Systems
Christian-Bürkert-Str. 13-17
D-74653 Ingelfingen
Tel. +49 (0)7940 10-91 111
E-mail: info@burkert.com
International: country.burkert.com



Manuals on the Internet / Bedienungsanleitungen im Internet / Manuels d'utilisation sur Internet :
country.burkert.com


Important information for devices with UL/UR approval

Operating conditions:

Type	Medium temperature	Ambient temperature	Medium
6518	-10 °C...+55 °C	-25 °C...+55 °C	Air
6519			

Ports - direction of flow:

All ports are marked with numbers on the valve body. The meaning of the numbers is the same for each variant.

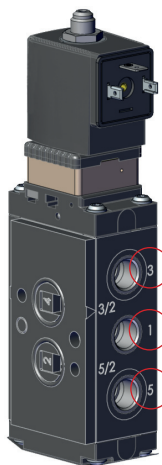

Number of the ports

Number	Meaning
1	Pressure port
2 and 4	Working port
3 and 5	Exhaust port
12 and 14	Pilot pressure port

MAN 1000652541 EN Version: - Status: RL (released | freigegeben) printed: 10.12.2024